

COMPACTA

1430POI038P60-46x38

EAN 4031582336672

Obrtni točkić, Kuciste od presovanog celika , pocinkovano, jedan venac kuglica u glavcini , osovina pertlovana, Priključak ploca.. Telo tocka od polipropilena, obican lezaj



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	38 mm
Sirina gazista.	16 mm
Sirina tocka	32 mm
Dimenzije ploce.	46 x 38 mm
Raspored rupa na ploci.	36 x 28 mm
Rupa na ploci.	5,3 mm
Kupola -Ø	32 mm
Dislokacija	13 mm
Otpor okretanju.	64 mm
Sveukupna visina.	50.5 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12528
Tezina	0.071 kg
Radius okretanja	32 mm
Tvrdoca omotaca	Shore D 65
Dinamicka nosivost.	25 kg
Staticka nosivost.	50 kg

Structure & Mounting

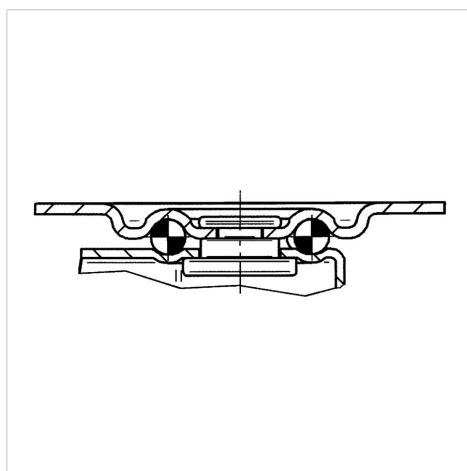

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○