

COMPACTA

1430PVH065P60-75x60

EAN 3700001796755

Swivel caster, housing made of pressed steel, bright zinc plated, blue passivated, single ball race swivel head, axle riveted, plate fitting. Wheel center made of Polypropylene, Tread: solid rubber, black, plain bearing, threadguard



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	65 mm
Wheel width	25 mm
Plate size	75 x 60 mm
Plate hole centers	55 x 40 mm
Plate hole	7 mm
Offset	25 mm
Swivel Interference	115 mm
Overall height	85 mm
Temperature	- 20 / + 60 °C
Standard	EN 12528
Weight	0.143 kg
Swivel Radius	57 mm
Hardness of tread	Shore D 65
Load capacity (dynamic)	40 kg
Load capacity (static)	80 kg

Structure & Mounting

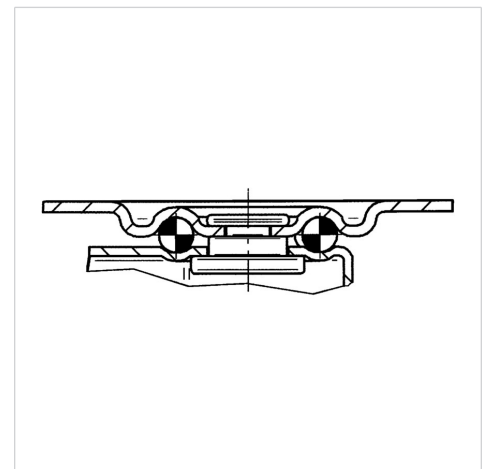

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○