

COMPACTA

2198UOI014P60-30x17

EAN 4031582030044

Fiksirani točkić, Viljuska od presovanog celika, pocinkovana, osovina osigurana, Priključak ploče..

Telo točka od poliamida , običan lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik točka.	14 mm
Sirina gazista.	14 mm
Sirina točka	20 mm
Dimenzije ploče.	30 x 17 mm
Raspored rupa na ploči.	20 mm
Rupa na ploči.	4 mm
Kupola -Ø	20 mm
Sveukupna visina.	17 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12528
Tezina	0.011 kg
Tvrdoća omotaca	Shore D 65
Dinamička nosivost.	25 kg
Statika nosivost.	50 kg

Dimensions

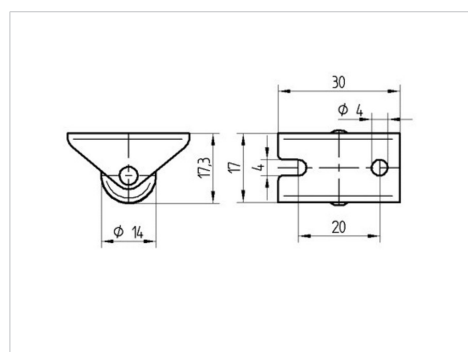

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○