

COMPACTA

2198UOI025P60-40x17

EAN 4031582300284

Fiksirani točkić, Viljuska od presovanog celika, pocinkovana, osovina osigurana, Priključak ploca..

Telo tocka od poliamida , obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	25 mm
Sirina gazista.	13 mm
Sirina tocka	20 mm
Dimenzije ploce.	40 x 17 mm
Raspored rupa na ploci.	30 mm
Rupa na ploci.	4,5 mm
Kupola -Ø	20 mm
Sveukupna visina.	28 mm
Temperatura	- 25 / - 25 °C
Standard	EN 12530
Tezina	0.018 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	25 kg
Staticka nosivost.	50 kg

Dimensions

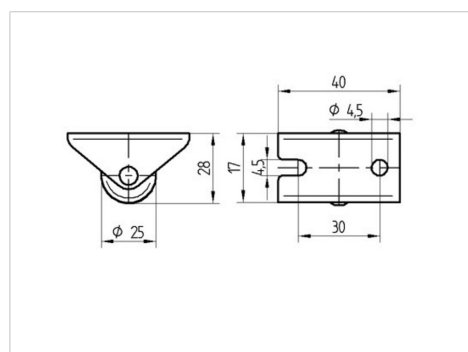

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○