

COMPACTA

2198UOI045P60-67x24

EAN 4031582030075

Fiksirani točkić, Viljuska od presovanog celika, pocinkovana, osovina osigurana, Priključak ploca..

Telo tocka od poliamida , obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	45 mm
Sirina gazista.	18 mm
Sirina tocka	20 mm
Dimenzije ploce.	67 x 24,0 mm
Raspored rupa na ploci.	54 mm
Rupa na ploci.	5,3 mm
Kupola -Ø	20 mm
Sveukupna visina.	48.5 mm
Temperatura	- 25 / + 80 °C
Standard	EN 12528
Tezina	0.063 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	40 kg
Staticka nosivost.	80 kg

Dimensions

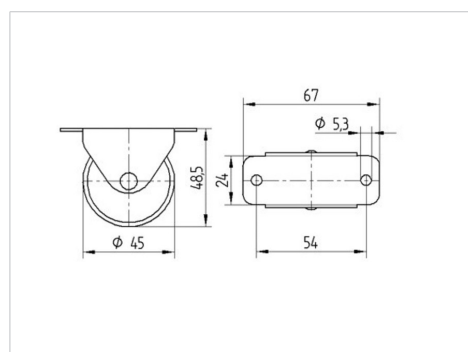

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○