

AGILA

2440JFX150R05-28

EAN 4031582300390

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, covered precision swivel bearing, hardened balls and tracks, bearing sleeve welded to fork, wheel axle with nut, solid plug fitting.



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	150 mm
Wheel width	32 mm
Bolt-Ø	28 mm
Bolt length	45 mm
Offset	50 mm
Swivel Interference	250 mm
Overall height	192.5 mm
Temperature	- 20 / + 85 °C
Standard	EN 12530
Weight	1.777 kg
Swivel Radius	125 mm
Hardness of tread	Shore A 75
Load capacity	150 kg
Load capacity (static)	300 kg

Dimensions

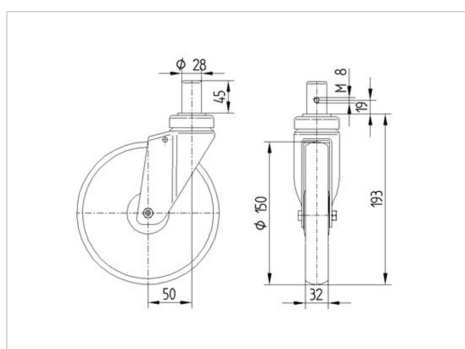

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○