

# AGILA

## 2478PJO075P60-67x60

EAN 4031582415841

Fixed castor, Fork made of pressed steel, bright zinc plated, blue passivated, plate fitting.

Wheel centre made of Polypropylene, Tread: TENTEprene (thermoplastic rubber), grey non-marking, plain bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	75 mm
Wheel width	25 mm
Size of Plate	67 x 60 mm
Plate hole centres	48/40 x 48/40 mm
Plate hole	6,3 mm
Overall height	100 mm
Temperature	- 20 / + 60 °C
Standard	EN 12530
Weight	0.16 kg
Hardness of tread	Shore A 87
Load capacity	75 kg
Load capacity (static)	150 kg

### Dimensions

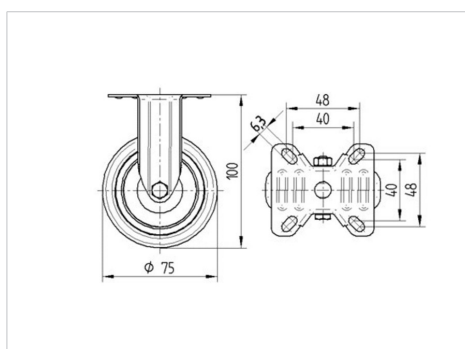

### Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○

# AGILA

2478PJO075P60-67x60

EAN 4031582415841



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

