

ALPHA

3430POI058P60-80x60

EAN 4031582303322

Obrtni točkić, Kuciste od presovanog celika , pocinkovano, jedan venac kuglica u glavcini , osovina pertlovana, Priključak ploca.. Telo tocka od polipropilena, obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	58 mm
Sirina gazista.	28 mm
Sirina tocka	50 mm
Dimenzije ploce.	80 x 60 mm
Raspored rupa na ploci.	60 x 40 mm
Rupa na ploci.	7,5 mm
Kupola -Ø	50.5 mm
Dislokacija	21 mm
Otpor okretanju.	100 mm
Sveukupna visina.	76 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	0.269 kg
Radius okretanja	50 mm
Tvrdoca omotaca	Shore D 65
Dinamicka nosivost.	100 kg
Staticka nosivost.	200 kg


Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

Dimensions

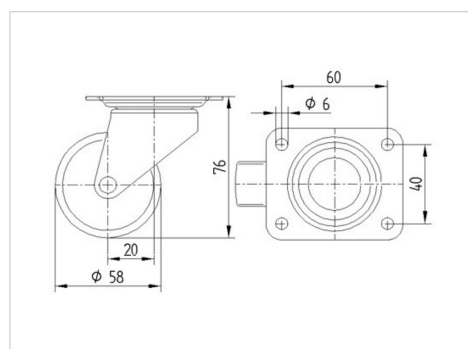

Structure & Mounting

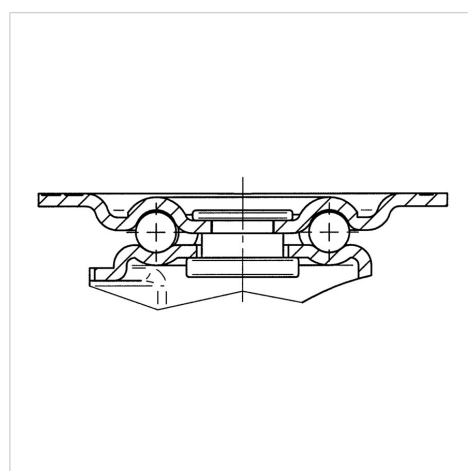

ALPHA

3430POI058P60-80x60

EAN 4031582303322



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

