



BETTER MOBILITY. BETTER LIFE.

3438POO065P60-95x54

EAN 4031582303346

Fiksirani točkić, Viljuska od presovanog celika, pocinkovana, osovina osigurana, Priključak ploca..

Telo tocka od polipropilena, obican lezaj




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	65 mm
Sirina gazista.	30 mm
Sirina tocka	54 mm
Dimenzije ploce.	95 x 54 mm
Raspored rupa na ploci.	71 x 24 mm
Rupa na ploci.	9 mm
Kupola -Ø	54 mm
Sveukupna visina.	83 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	0.234 kg
Tvrdoca omotaca	Shore D 65
Dinamicka nosivost.	120 kg
Staticka nosivost.	240 kg

Dimensions

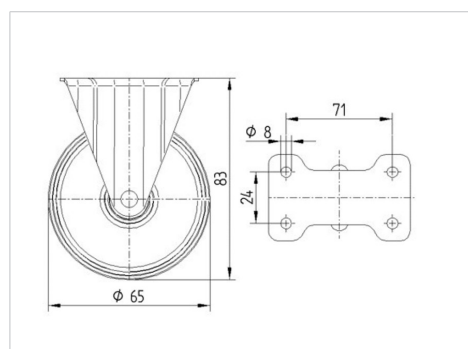

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○



BETTER MOBILITY. BETTER LIFE.

3438POO065P60-95x54

EAN 4031582303346

Structure & Mounting

