

ALPHA

3470PVO080P30-13

EAN 4031582304084

Obrtni točkić, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak.
Telo tocka od polipropilena, Omotac: tvrda guma , crna , obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

| | |
|---------------------|----------------|
| Precnik tocka. | 80 mm |
| Sirina gazista. | 35 mm |
| Centralna rupa. | 13 mm |
| Dislokacija | 40 mm |
| Otpor okretanju. | 160 mm |
| Sveukupna visina. | 108 mm |
| Temperatura | - 20 / + 60 °C |
| Standard | EN 12532 |
| Tezina | 0.743 kg |
| Radijus okretanja | 80 mm |
| Tvrdoca omotaca | Shore A 85 |
| Dinamicka nosivost. | 70 kg |
| Staticka nosivost. | 140 kg |

Advantages at a glance

| | |
|---------------------|-----------|
| Otpor okretanju | ● ● ○ ○ ○ |
| Buka pri okretanju | ● ● ● ○ ○ |
| trenje , habanje | ● ● ○ ○ ○ |
| zastita od korozije | ● ● ● ○ ○ |

Dimensions

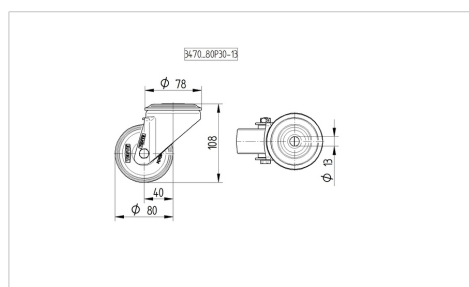

Structure & Mounting

