

# ALPHA

3470PVR080P30-13

EAN 4031582304183

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel centre made of Polypropylene, Tread: solid rubber, black, roller bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


## Technical Data

Wheel diameter	80 mm
Wheel width	35 mm
Centre hole	13 mm
Offset	40 mm
Swivel Interference	160 mm
Overall height	108 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	0.759 kg
Swivel Radius	80 mm
Hardness of tread	Shore A 85
Load capacity	70 kg
Load capacity (static)	320 kg

## Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ○ ○ ○
Corrosion resistance	● ● ● ○ ○

## Dimensions

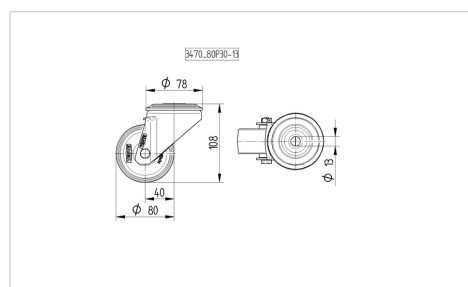

## Structure & Mounting

