

ALPHA

3470PVR100P30-13

EAN 4031582304190

Obrtni točkić, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglični lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak.
Telo tocka od polipropilena, Omotac: tvrda guma, crna , valjkasti lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	100 mm
Sirina gazista.	35 mm
Centralna rupa.	13 mm
Dislokacija	40 mm
Otpor okretanju.	180 mm
Sveukupna visina.	128 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	0.869 kg
Radijus okretanja	90 mm
Tvrdoca omotaca	Shore A 85
Dinamicka nosivost.	75 kg
Staticka nosivost.	320 kg

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○

Dimensions

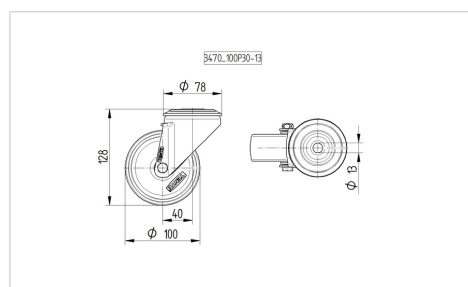

Structure & Mounting

