

ALPHA

3470UER160P30-13

EAN 4031582304350

Swivel caster, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel center made of Polyamide, Tread: elastic-tire, black, roller bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Technical Data

Wheel diameter	160 mm
Wheel width	46 mm
Center hole	13 mm
Offset	55 mm
Swivel Interference	270 mm
Overall height	195 mm
Temperature	- 20 / + 80 °C
Standard	EN 12532
Weight	1.954 kg
Swivel Radius	135 mm
Hardness of tread	Shore A 64
Load capacity (dynamic)	200 kg
Load capacity (static)	400 kg

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ● ●
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ○ ○

Dimensions

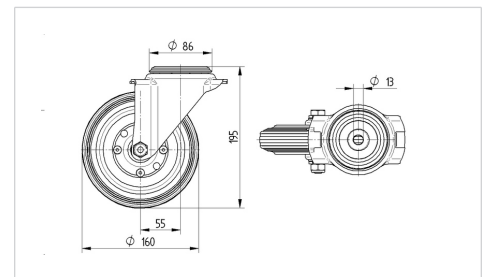

Structure & Mounting

