

ALPHA

3470UER160P30-13

EAN 4031582304350

Obrtni točkić, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglični lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak.
Telo tocka od poliamida, Omotac: elasticna guma , crna , valjkasti lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	160 mm
Sirina gazista.	46 mm
Centralna rupa.	13 mm
Dislokacija	55 mm
Otpor okretanju.	270 mm
Sveukupna visina.	195 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	1.954 kg
Radijus okretanja	135 mm
Tvrdoca omotaca	Shore A 64
Dinamicka nosivost.	200 kg
Staticka nosivost.	400 kg

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ●
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○

Dimensions

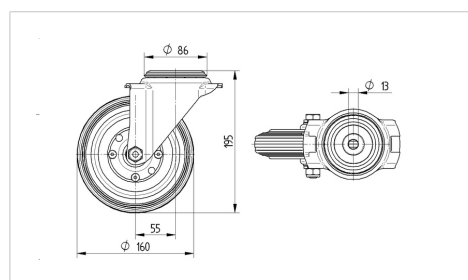

Structure & Mounting

