

ALPHA

3476UFP200P67

EAN 4031582305012

Okretni točak sa centralnom kocnicom, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, stitnik od prasine, montaza sa plocom i integrisanom centralnom kocnicom. Telo tocka od poliamida , Omotac: elasticka guma , ne ostavlja trag , precizni kuglicni lezaj
Hint: Pedala kocnice se nalazi na montaznoj ploci. Okretni mehanizam je nezavisan na montaznoj ploci. Samim tim je položaj kocione pedale uvek isti.

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	200 mm
Sirina gazista.	46 mm
Sirina tocka	99 mm
Dimenzije ploce.	176 x 112 mm
Raspored rupa na ploci.	105 x 77,5 mm
Rupa na ploci.	13 mm
Kupola -Ø	96 mm
Dislokacija	55 mm
Otpor okretanju.	287 mm
Sveukupna visina.	240 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	3.133 kg
Radijus okretanja	143.5 mm
Tvrdoca omotaca	Shore A 63
Dinamicka nosivost.	300 kg
Staticka nosivost.	600 kg


Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ●
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○

Dimensions

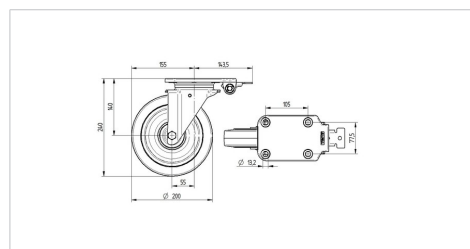

Structure & Mounting

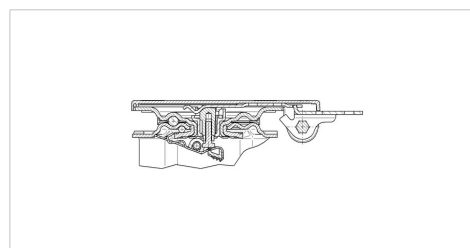

ALPHA

3476UFP200P67

EAN 4031582305012



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

