

# ALPHA

## 3477PVO080P30-13

EAN 4031582305579

Okretni tocak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak. Telo tocka od polipropilena, Omotac: tvrda guma , crna , obican lezaj

# TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	35 mm
Sirina tocka	75 mm
Centralna rupa.	13 mm
Kupola -Ø	75 mm
Dislokacija	44.5 mm
Otpor okretanju.	242 mm
Sveukupna visina.	108 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	0.833 kg
Radius okretanja	121 mm
Tvrdoća omotaca	Shore A 80
Dinamička nosivost.	80 kg
Statička nosivost.	160 kg

### Advantages at a glance

Otpor okretanju	● ● ○ ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○

### Dimensions

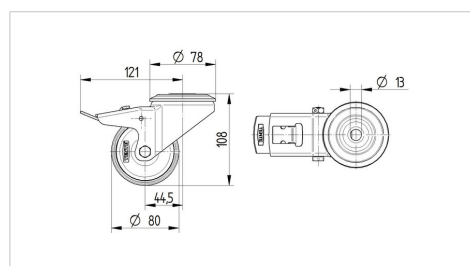

### Structure & Mounting

