

ALPHA

3477PVO080P62

EAN 4031582305586

Okretni tocak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, stitnik od prasine, Prikljucak ploca.. Telo tocka od polipropilena, Omotac: tvrda guma , crna , obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

| | |
|-------------------------|----------------|
| Precnik tocka. | 80 mm |
| Sirina gazista. | 35 mm |
| Sirina tocka | 75 mm |
| Dimenzije ploce. | 105 x 80 mm |
| Raspored rupa na ploci. | 80/77 x 60 mm |
| Rupa na ploci. | 9 mm |
| Kupola -Ø | 75 mm |
| Dislokacija | 44.5 mm |
| Otpor okretanju. | 242 mm |
| Sveukupna visina. | 108 mm |
| Temperatura | - 20 / + 60 °C |
| Standard | EN 12532 |
| Tezina | 0.919 kg |
| Radius okretanja | 121 mm |
| Tvrdoca omotaca | Shore A 80 |
| Dinamicka nosivost. | 70 kg |
| Staticka nosivost. | 140 kg |


Advantages at a glance

| | |
|---------------------|-------------|
| Otpor okretanju | ● ● ○ ○ ○ ○ |
| Buka pri okretanju | ● ● ● ○ ○ ○ |
| trenje , habanje | ● ● ○ ○ ○ ○ |
| zastita od korozije | ● ● ● ○ ○ ○ |

Dimensions

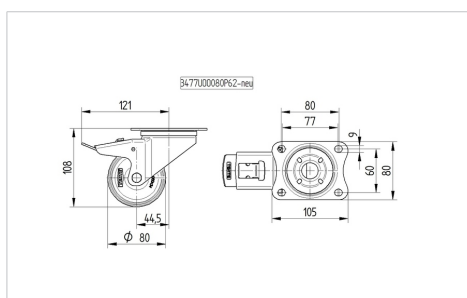

Structure & Mounting

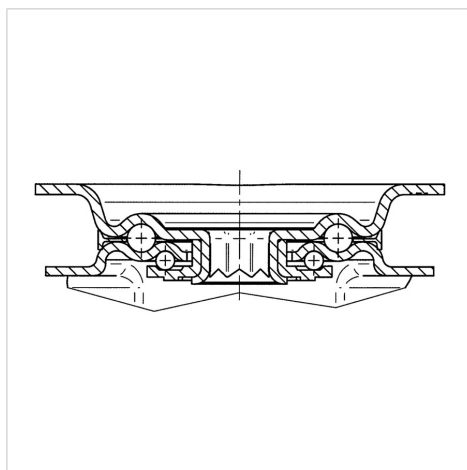

ALPHA

3477PVO080P62

EAN 4031582305586



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

