

# ALPHA

3477PVO200P30-13

EAN 4031582305654

Swivel caster with total lock, trailing end of caster, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel center made of Polypropylene, Tread: solid rubber, black, plain bearing



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


## Technical Data

Wheel diameter	200 mm
Wheel width	50 mm
Center hole	13 mm
Offset	55 mm
Swivel Interference	332 mm
Overall height	235 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	2.986 kg
Swivel Radius	166 mm
Hardness of tread	Shore A 85
Load capacity (dynamic)	200 kg
Load capacity (static)	400 kg

## Advantages at a glance

Roll performance	● ● ○ ○ ○ ○
Movement noise	● ● ● ○ ○ ○
Attrition	● ● ○ ○ ○ ○
Corrosion resistance	● ● ● ○ ○ ○

## Dimensions

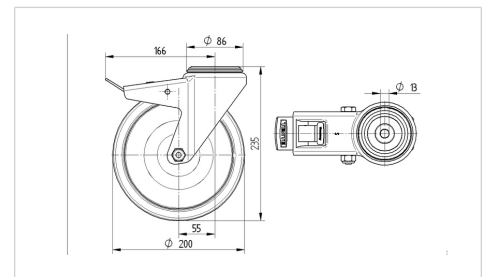

## Structure & Mounting

