

ALPHA

3477PVR100P30-13

EAN 4031582305685

Okretni točak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak. Telo tocka od polipropilena, Omotac: tvrda guma, crna , valjkasti lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	100 mm
Sirina gazista.	35 mm
Centralna rupa.	13 mm
Dislokacija	41 mm
Otpor okretanju.	242 mm
Sveukupna visina.	128 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	1.014 kg
Radijus okretanja	121 mm
Tvrdoca omotaca	Shore A 85
Dinamicka nosivost.	75 kg
Staticka nosivost.	150 kg

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○

Dimensions

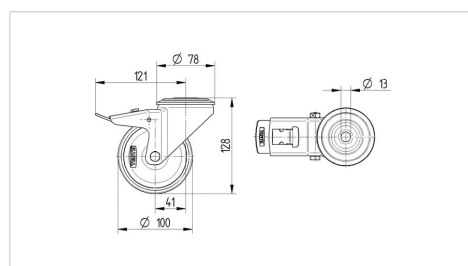

Structure & Mounting

