

# ALPHA

## 3477PVR160P30-13

EAN 4031582305715

Okretni tocak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od presovanog celika, pocinkovano , dupli kuglicni lezaj u okretnoj glavi, osovina tocka sa caurom, rupa za vijak. Telo tocka od polipropilena, Omotac: tvrda guma, crna , valjkasti lezaj

**TENTE**

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Tehnicki podaci

Precnik tocka.	160 mm
Sirina gazista.	40 mm
Sirina tocka	96 mm
Centralna rupa.	13 mm
Kupola -Ø	96 mm
Dislokacija	60 mm
Otpor okretanju.	334 mm
Sveukupna visina.	195 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	2.236 kg
Radijus okretanja	167 mm
Tvrdoća omotaca	Shore A 80
Dinamička nosivost.	135 kg
Statička nosivost.	270 kg

### Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○

### Dimensions

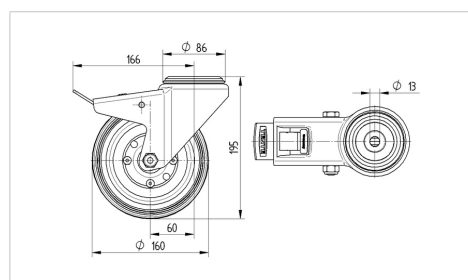

### Structure & Mounting

