

# LEVINA

## 5377PJP125P30-11

EAN 4031582368758

Okretni točak sa potpunom kocnicom , zadnji deo tocka, Kucliste i točkovi napravljeni od visoko kvalitetnih sintetičkih materijala, dupli kuglični lezajevi u okretnoj glavi, rupa za vijak. Telo tocka od polipropilena, Omotac: TENTEprene (termoplasticna guma), siva - ne ostavlja trag , precizni kuglični lezaj

Hint: Ovi točkovi su na raspolaganju i sa sivom polugom za blokadu



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Tehnicki podaci

Precnik tocka.	125 mm
Sirina gazista.	32 mm
Sirina tocka	59 mm
Centralna rupa.	11 mm
Kupola -Ø	59 mm
Dislokacija	38 mm
Otpor okretanju.	201 mm
Sveukupna visina.	161 mm
Temperatura	- 10 / + 40 °C
Standard	EN 12530
Tezina	0.579 kg
Radijus okretanja	100.5 mm
Tvrdoca omotaca	Shore A 87
Dinamicka nosivost.	100 kg
Staticka nosivost.	200 kg


### Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ○
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ● ○

### Dimensions

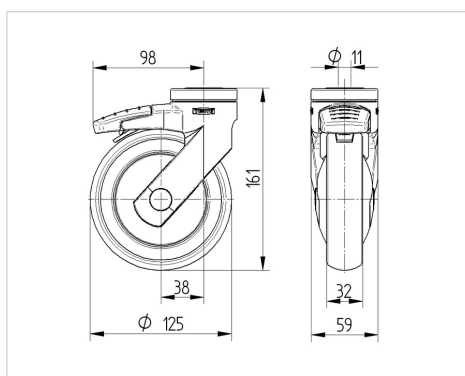

### Structure & Mounting

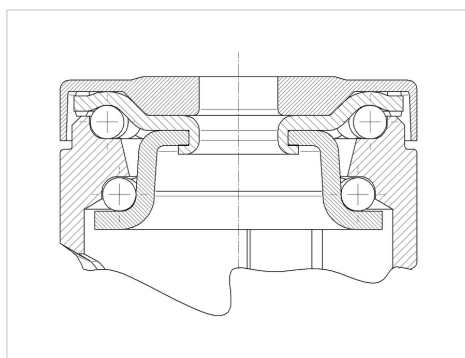

# LEVINA

5377PJP125P30-11

EAN 4031582368758



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

---

