

ALPHA

8477UFX100P30-13

EAN 4031582339383

Okretni tocak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od nerdjajuceg celika, dupli kuglicni lezajevi u okretnoj glavi, osovina sa caurom, rupa za vijak. Telo tocka od poliamida , Omotac: elasticka guma , ne ostavlja trag , sa malim ratkapnama , prezicni kuglicni lezaj , zatvoren.

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	100 mm
Sirina gazista.	34 mm
Sirina tocka	75 mm
Centralna rupa.	13 mm
Kupola -Ø	75 mm
Dislokacija	41 mm
Otpor okretanju.	246 mm
Sveukupna visina.	128 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	0.92 kg
Radijus okretanja	123 mm
Tvrdoca omotaca	Shore A 63
Dinamicka nosivost.	160 kg
Staticka nosivost.	320 kg

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ●
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ● ●

Dimensions

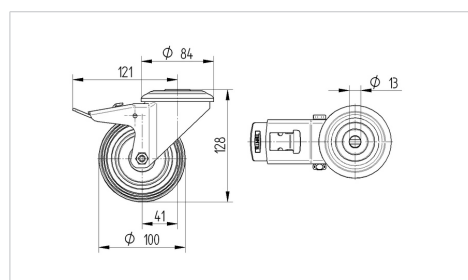

Structure & Mounting

