

# ALPHA

## 8477U00080P30-13

EAN 4031582313062

Okretni tocak sa potpunom kocnicom , zadnji deo tocka, Kuciste napravljeno od nerdjajuceg celika, dupli kuglicni lezajevi u okretnoj glavi, osovina sa caurom, rupa za vijak. Telo tocka od poliamida , obican lezaj

**TENTE**

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	34 mm
Sirina tocka	75 mm
Centralna rupa.	13 mm
Kupola -Ø	75 mm
Dislokacija	44.5 mm
Otpor okretanju.	246 mm
Sveukupna visina.	108 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12532
Tezina	0.698 kg
Radijus okretanja	123 mm
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	150 kg
Staticka nosivost.	300 kg

### Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ● ●

### Dimensions

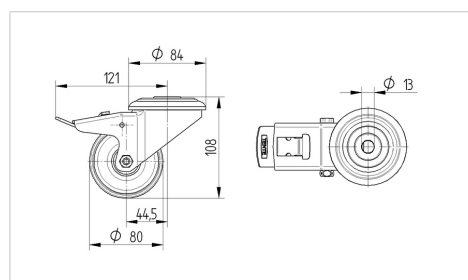

### Structure & Mounting

