

# ALPHA

## 8478U00080P62

EAN 4031582313383

Fiksirani točkić, Viljuska napravljena od nerdjajućeg celika, osovina tocka sa maticom, Priključak ploca..

Telo tocka od poliamida , obican lezaj

# TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	34 mm
Sirina tocka	85 mm
Dimenzije ploce.	100 x 85 mm
Raspored rupa na ploci.	80/77 x 60 mm
Rupa na ploci.	9 mm
Sveukupna visina.	108 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12532
Tezina	0.376 kg
Tvrdoća omotaca	Shore D 75
Dinamička nosivost.	200 kg
Statička nosivost.	400 kg

### Dimensions

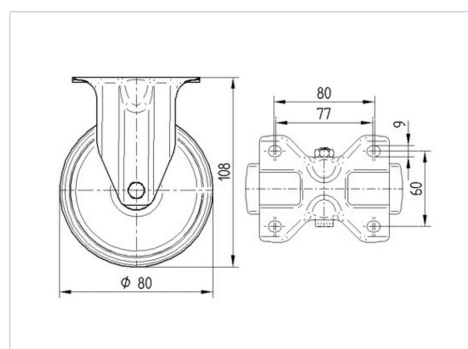

### Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ● ●

# ALPHA

8478U00080P62

EAN 4031582313383



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

