

ZETA**8678TOO125P63**

EAN 4031582313857

Fiksirani točkić, Viljuska napravljena od nerdjajućeg celika, osovina tocka sa maticom, Priključak ploca..

Telo tocka od poliamida, visoke nosivosti, obican lezaj

TENTE

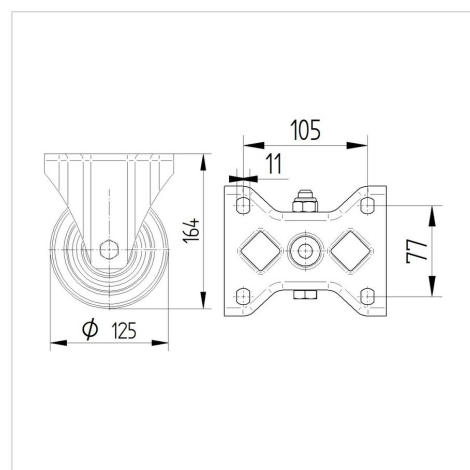
BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product

Tehnicki podaci

Precnik tocka.	125 mm
Sirina gazista.	50 mm
Sirina tocka	117 mm
Dimenzije ploce.	137 x 117,0 mm
Raspored rupa na ploci.	105 x 80/74 mm
Rupa na ploci.	11 mm
Sveukupna visina.	164 mm
Temperatura	- 30 / + 80 °C
Standard	EN 12533
Tezina	1.495 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	700 kg
Staticka nosivost.	1400 kg

Dimensions**Advantages at a glance**

Otpor okretanju	● ● ● ● ●
Buka pri okretanju	● ○ ○ ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ● ●

ZETA

8678TOO125P63

EAN 4031582313857



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

