

OMIKRON

9250FTP300P66

EAN 4031582314014

Obrtni točkić, Kuciste i ploca su zavareni, pocinkovani, zapečaceni okretni lezajevi sa duplom svrhom i valjkastim lezajem, lozovan klin ,mazalica i osovina tocka sa maticom, Prikljucak ploca.. Telo tocka napravljeno od livenog gvozdja, Omotac: poliuretana, precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	300 mm
Sirina gazista.	100 mm
Sirina tocka	182 mm
Dimenzije ploce.	250 x 200 mm
Raspored rupa na ploci.	210 x 160 mm
Rupa na ploci.	17 mm
Kupola -Ø	160 mm
Dislokacija	90 mm
Otpor okretanju.	490 mm
Sveukupna visina.	370 mm
Temperatura	- 10 / + 60 °C
Standard	EN 12533
Tezina	40.964 kg
Radius okretanja	245 mm
Tvrdoca omotaca	Shore D 42
Dinamicka nosivost.	3120 kg
Staticka nosivost.	6240 kg


Advantages at a glance

Otpor okretanju	● ● ● ● ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ○
zastita od korozije	● ● ● ○ ○

Dimensions

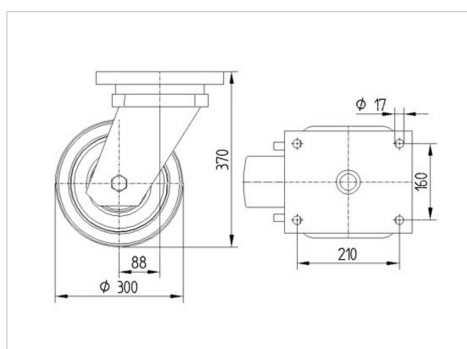

Structure & Mounting

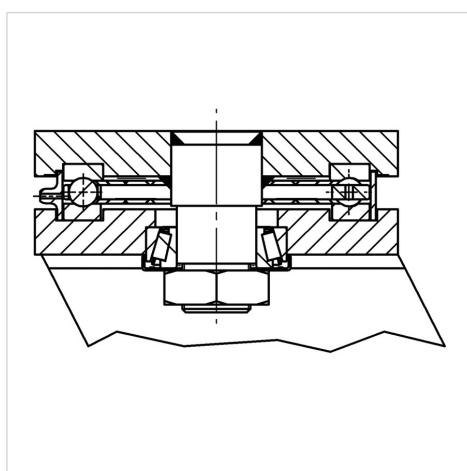

OMIKRON

9250FTP300P66

EAN 4031582314014



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

