

KAPPA

9682TOO250P63

EAN 4031582316025

Okretan točak sa potpunom kocnicom , prednji deo točka, Kuciste i ploča su zavareni, pocinkovani, zapecaceni dupli okretni kuglicni lezajevi , lozovan klin ,mazalica i osovina točka sa maticom, Priključak ploča.. Telo točka od poliamida, visoke nosivosti, obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik točka.	250 mm
Sirina gazista.	50 mm
Dimenzije ploče.	135 x 110 mm
Raspored rupa na ploči.	105 x 80/75 mm
Rupa na ploči.	11 mm
Dislokacija	61 mm
Otpor okretanju.	372 mm
Sveukupna visina.	305 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12533
Težina	5.29 kg
Tvrdoća omotaca	Shore D 75
Dinamička nosivost.	1000 kg
Statika nosivost.	2000 kg


Advantages at a glance

Otpor okretanju	● ● ● ● ●
Buka pri okretanju	● ○ ○ ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

Dimensions

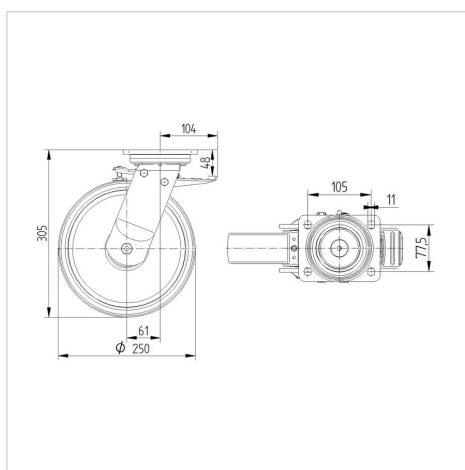

Structure & Mounting

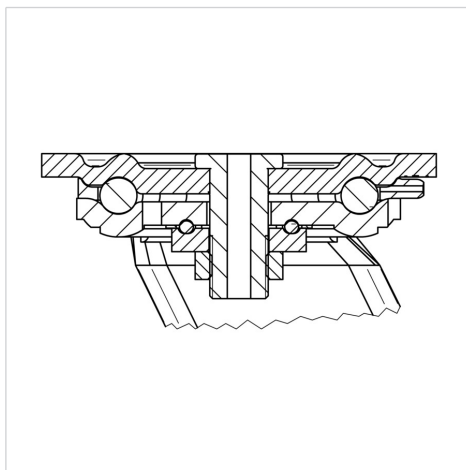

KAPPA

9682TOO250P63

EAN 4031582316025



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

