

DELTA TWIN

9940ETP065P41-100x100

EAN 4031582501162

Obrtni točkić, Kuciste napravljeno od tesko presovanog celika, plavo pocinkovano, precizni kuglicni lezaj u okretnoj glavi, zatvoren, osovina tocka sa caurom., Prikljucak ploca.. Telo tocka napravljeno od celika, Omotac: poliuretan, liveni sa preciznim kuglicnim lezaj



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Tehnicki podaci

Precnik tocka.	65 mm
Sirina gazista.	30 mm
Sirina tocka	92 mm
Dimenzije ploce.	100 x 100,0 mm
Raspored rupa na ploci.	105 x 78 mm
Rupa na ploci.	10,5 mm
Kupola -Ø	73 mm
Dislokacija	25 mm
Otpor okretanju.	128 mm
Sveukupna visina.	111.5 mm
Temperatura	- 30 / + 60 °C
Standard	EN 12532
Tezina	1.932 kg
Radius okretanja	64 mm
Tvrdoca omotaca	Shore D 42
Dinamicka nosivost.	400 kg
Staticka nosivost.	800 kg


Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ○
zastita od korozije	● ● ● ○ ○

Dimensions

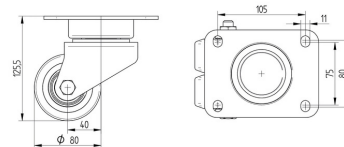

Structure & Mounting

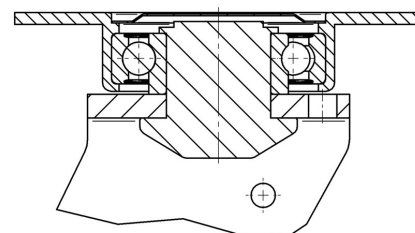

DELTA TWIN

9940ETP065P41-100x100

EAN 4031582501162



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

