

OMIKRON TWIN

9958FTP250P68

EAN 4031582316995

Fiksirani točkić, Viljuska i ploca zavareni, pocinkovani, osovina tocka sa caurom, Priključak ploca..

Telo tocka napravljeno od livenog gvozdja, Omotac: poliuretan, precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	250 mm
Sirina gazista.	80 mm
Sirina tocka	272 mm
Dimenzije ploce.	270 x 250 mm
Raspored rupa na ploci.	230 x 210 mm
Rupa na ploci.	17 mm
Kupola -Ø	235 mm
Sveukupna visina.	365 mm
Temperatura	- 10 / + 60 °C
Standard	EN 12533
Tezina	38.319 kg
Tvrdoca omotaca	Shore D 42
Dinamicka nosivost.	4320 kg
Staticka nosivost.	8640 kg

Dimensions

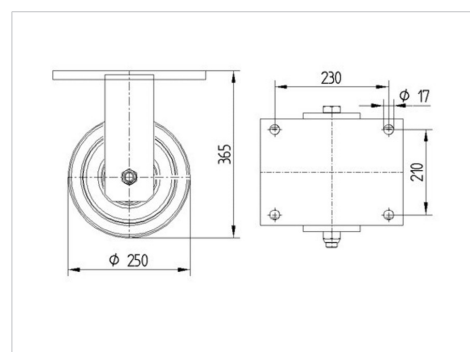

Advantages at a glance

Otpor okretanju	● ● ● ● ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ○
zastita od korozije	● ● ● ○ ○

OMIKRON TWIN

9958FTP250P68

EAN 4031582316995



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

