

OMIKRON TWIN

9958TOP100P65

EAN 4031582317046

Fiksirani točkić, Viljuska i ploca zavareni, pocinkovani, osovina tocka sa caurom, Priključak ploca..

Telo tocka od poliamida, visoke nosivosti, precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

| | |
|-------------------------|----------------|
| Precnik tocka. | 100 mm |
| Sirina gazista. | 50 mm |
| Sirina tocka | 189 mm |
| Dimenzije ploce. | 200 x 160 mm |
| Raspored rupa na ploci. | 160 x 120 mm |
| Rupa na ploci. | 15 mm |
| Kupola -Ø | 160 mm |
| Sveukupna visina. | 180 mm |
| Temperatura | - 40 / + 85 °C |
| Standard | EN 12533 |
| Tezina | 7.225 kg |
| Tvrdoca omotaca | Shore D 75 |
| Dinamicka nosivost. | 1440 kg |
| Staticka nosivost. | 2880 kg |

Dimensions

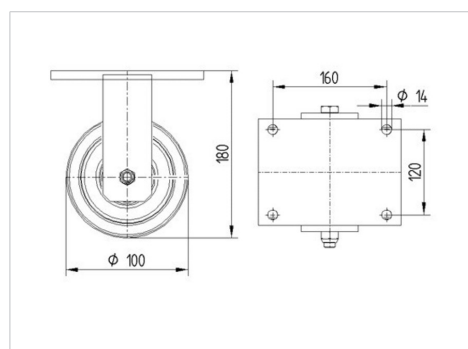

Advantages at a glance

| | |
|---------------------|-----------|
| Otpor okretanju | ● ● ● ● ● |
| Buka pri okretanju | ● ● ● ○ ○ |
| trenje , habanje | ● ● ● ● ● |
| zastita od korozije | ● ● ● ○ ○ |

OMIKRON TWIN

9958TOP100P65

EAN 4031582317046



BETTER MOBILITY. BETTER LIFE.

Structure & Mounting

