

# ICS

5328UAP100R05-18X62

EAN 4031582310290  
Order number 00030106



BETTER MOBILITY. BETTER LIFE.



Image may differ from the original product

## PERFORMANCE

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ● ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ● ○

## CORE ATTRIBUTES

Product name	ICS
Housing type	Fixed castor
Standard	EN12530 - Devices Castors
Load capacity at 3 km/h	100 kg
Load capacity Static	200 kg
Temperature range (Minimum)	-10 °C
Temperature range (Maximum)	40 °C
Overall height	137 mm
Overall weight	0.52 kg

## WHEEL

Body material	Polyamide
Tread material	Polyurethane, injected
Bearing	Precision ball bearing
Threadguards	Integrated threadguard
Diameter	100 mm
Tread width	32 mm
Hardness of tread (D)	42 Shore D

## HOUSING

Material	Polyamide
Fork shape	Slim

## FITTING

Fitting type	Solid stem, round
Bolt diameter	18 mm
Bolt length	62 mm



# ICS


5328UAP100R05-18X62

EAN 4031582310290  
Order number 00030106



BETTER MOBILITY. BETTER LIFE.

## TECHNICAL DRAWINGS

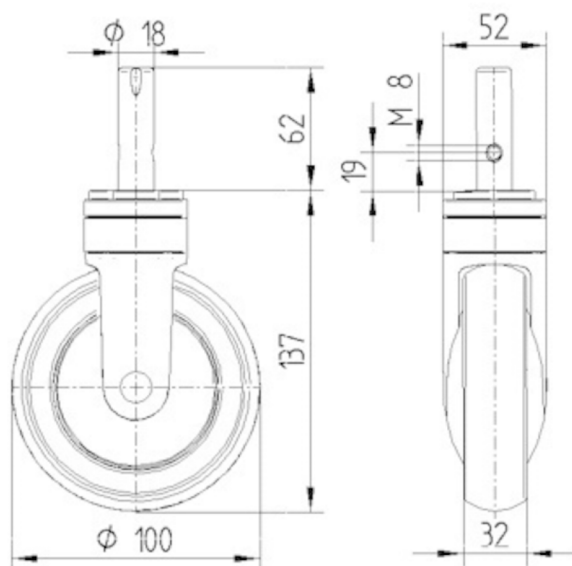

IF  
Design  
Award