

PURETECH

DIK075x25-Ø6

EAN 4031582070149

Telo tocka je napravljeno od presovanog celika. Omotac: cvrsta guma, siva
- ne ostavlja trag, sa ratkapnama , konusni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	75 mm
Sirina gazista.	25 mm
Otvor za osovinu Ø	6 mm
Duzina glavcine.	28 mm
Temperatura	- 20 / + 85 °C
Standard	EN 12530
Tezina	0.22 kg
Tvrdoca omotaca	Shore A 80
Dinamicka nosivost.	55 kg
Staticka nosivost.	110 kg

Dimensions

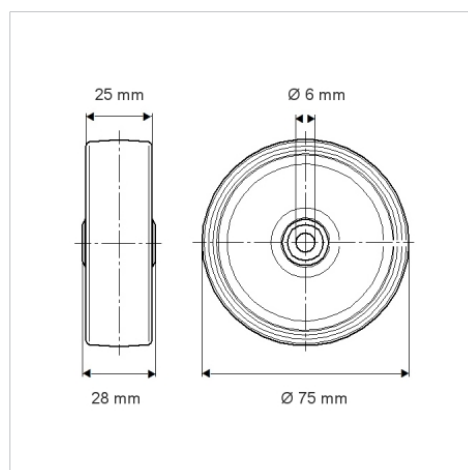

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○