

NOVATECH

FTP400x80-Ø40 HL90

EAN 4031582319507

Wheel centre made of cast iron, Tread: Polyurethane, casted, precision ball bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	400 mm
Wheel width	80 mm
Axle Hole-Ø	40 mm
Hub length	90 mm
Temperature	- 10 / + 60 °C
Standard	EN 12533
Weight	23.598 kg
Hardness of tread	Shore D 42
Load capacity	2500 kg
Load capacity (static)	5000 kg

Dimensions

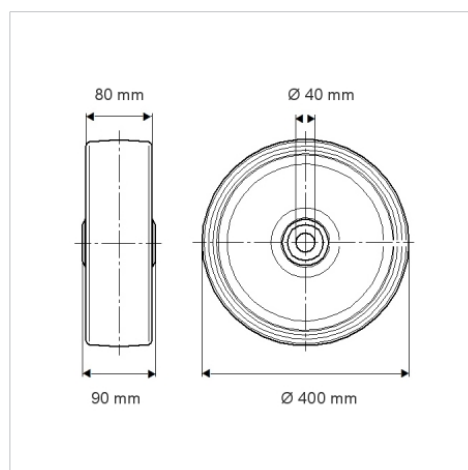

Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ○
Corrosion resistance	● ● ● ○ ○

Structure & Mounting

