

DURATECH PLUS

MOP150x50-Ø30

EAN 4031582320022

Telo tocka od poliamida, model extra visoke nosivosti, precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	150 mm
Sirina gazista.	50 mm
Otvor za osovinu Ø	30 mm
Duzina glavcine.	60 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12533
Tezina	1.446 kg
Tvrdoca omotaca	Shore D 75
Bearing	6306 Br.
Dinamicka nosivost.	2100 kg
Staticka nosivost.	4200 kg

Dimensions

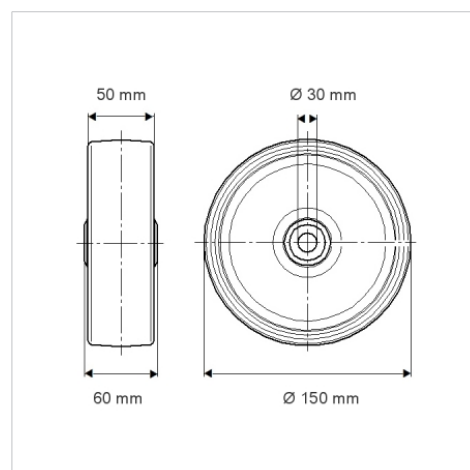

Advantages at a glance

Otpor okretanju	● ● ● ● ●
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

Structure & Mounting

