

# DURATECH PLUS

## MOP160x50-Ø30

EAN 4031582320046

Telo tocka od poliamida, model extra visoke nosivosti, precizni kuglicni lezaj

**TENTE**

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


### Tehnicki podaci

Precnik tocka.	160 mm
Sirina gazista.	50 mm
Otvor za osovinu Ø	30 mm
Duzina glavcine.	60 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12533
Tezina	1.616 kg
Tvrdoca omotaca	Shore D 75
Bearing	6306 Br.
Dinamicka nosivost.	2250 kg
Staticka nosivost.	4500 kg

### Advantages at a glance

Otpor okretanju	● ● ● ● ●
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

### Dimensions

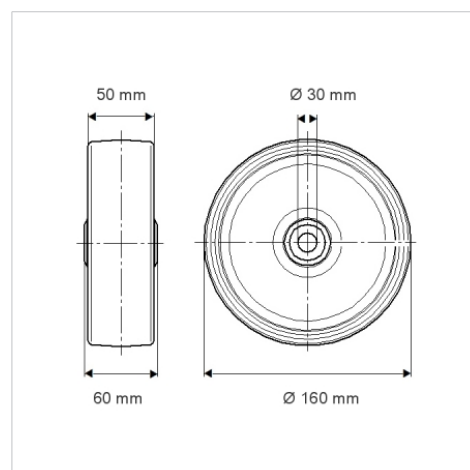

### Structure & Mounting

