

DURATECH PLUS

MOP200x50-Ø35

EAN 4031582320053

Telo tocka od poliamida, model extra visoke nosivosti, precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	200 mm
Sirina gazista.	50 mm
Otvor za osovinu \varnothing	35 mm
Duzina glavcine.	60 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12533
Tezina	2.578 kg
Tvrdoca omotaca	Shore D 75
Bearing	6307 Br.
Dinamicka nosivost.	2800 kg
Staticka nosivost.	5600 kg

Dimensions

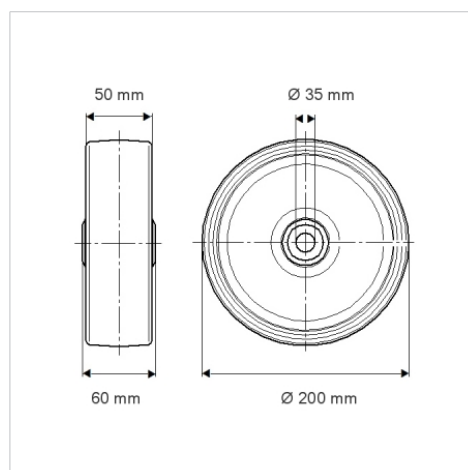

Advantages at a glance

Otpor okretanju	● ● ● ● ●
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

Structure & Mounting

