

# SUPRATECH

PJP075x25-Ø6

EAN 4031582070248

Telo točka od polipropilena, Omotac: TENTEprene (termoplasticna guma), siva - ne ostavlja trag , precizni kuglicni lezaj, sa ratkapnama



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

## Tehnicki podaci

Precnik tocka.	75 mm
Sirina gazista.	25 mm
Otvor za osovinu Ø	6.3 mm
Duzina glavcine.	28.2 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12530
Tezina	0.094 kg
Tvrdoca omotaca	Shore A 87
Dinamicka nosivost.	75 kg
Staticka nosivost.	150 kg

## Dimensions

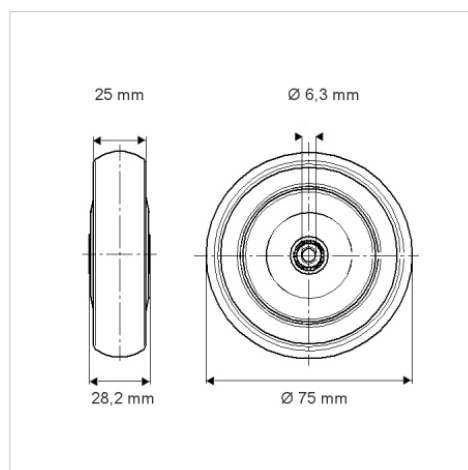

## Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○