

BASETECH

POO080x34-Ø12 RAL9011

EAN 4031582320732

Wheel center made of Polypropylene, plain bearing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	80 mm
Wheel width	34 mm
Axle Hole-Ø	12.1 mm
Hub length	44.4 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	0.064 kg
Hardness of tread	Shore D 65
Load capacity (dynamic)	125 kg
Load capacity (static)	250 kg

Dimensions

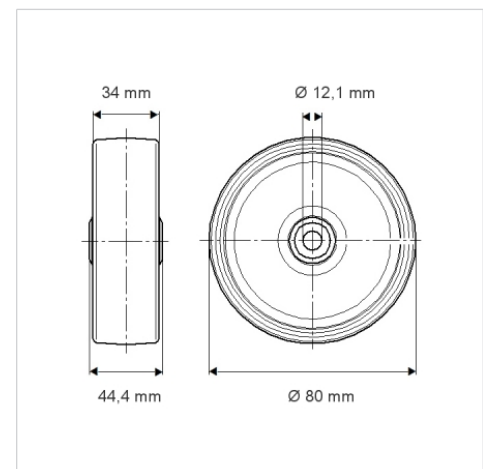

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ○ ○