

# PURETECH

## PVR080x35-Ø12

EAN 4031582321241

Telo točka od polipropilena, Omotac: tvrda guma, crna , valjkasti lezaj

**TENTE**

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	35 mm
Otvor za osovinu Ø	12 mm
Duzina glavcine.	44.4 mm
Temperatura	- 20 / + 60 °C
Standard	EN 12532
Tezina	0.164 kg
Tvrdoca omotaca	Shore A 80
Dinamicka nosivost.	70 kg
Staticka nosivost.	140 kg

### Dimensions

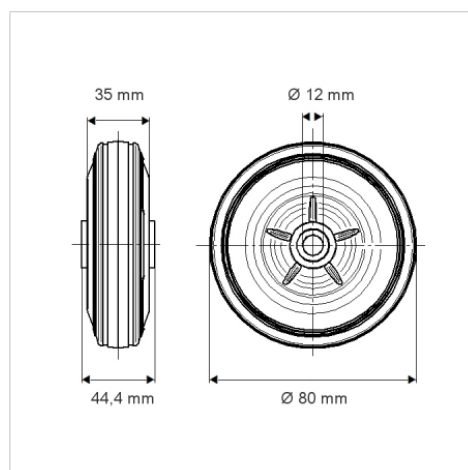

### Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○