

R48-36-Ø28

EAN 4031582321807

bucșă de reducere (pătrată)



BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


Date Tehnice

| | |
|---------------|----------|
| Diametru bolț | 28 mm |
| Lungime bolț | 60 mm |
| Greutate | 0.047 kg |

Advantages at a glance

| | |
|-----------------------------|-----------|
| Rezistență la rulare | ○ ○ ○ ○ ○ |
| Zgomot de mișcare | ○ ○ ○ ○ ○ |
| Uzare | ○ ○ ○ ○ ○ |
| Protecție împotriva ruginii | ● ● ● ○ ○ |

Dimensions

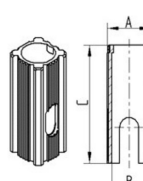

| Bezeichnung | A | B | C |
|--------------|------|-----|----|
| R48-225-Ø18 | 226 | Ø18 | 62 |
| R48-275-Ø18 | 275 | Ø18 | 62 |
| R48-27-Ø22 | 27 | Ø22 | 45 |
| R48-32-Ø22 | 32 | Ø22 | 45 |
| R48-36-Ø22 | 36 | Ø22 | 60 |
| R48-32-Ø28 | 32 | Ø28 | 45 |
| R48-3365-Ø28 | 3365 | Ø28 | 45 |
| R48-36-Ø28 | 36 | Ø28 | 60 |