

SOCKET

PLASTIC SOCKET R40-16/11

EAN 4031582090154
Broj porudžbine 00009042



BETTER MOBILITY. BETTER LIFE.



Slika se može razlikovati od originalnog proizvoda

PERFORMANSE

otpornost na rdju



OSNOVNI ATRIBUTI

| | |
|--------------------|----------|
| Naziv proizvoda | Socket |
| Tip kućišta | pribor |
| Nosivost na 3 km/h | 40 kg |
| Statički Nosivost | 80 kg |
| Sveukupna visina | 36 mm |
| Ukupna težina | 0,004 kg |

PRILAGOĐAVANJE

| | |
|---------------|------------------------------|
| Tip uklapanja | Sintetička uticnica, kvadrat |
| Prečnik sraf | 16 mm |

SOCKET


PLASTIC SOCKET R40-16/11

EAN 4031582090154
Broj porudžbine 00009042



BETTER MOBILITY. BETTER LIFE.

TEHNIČKI CRTEŽI

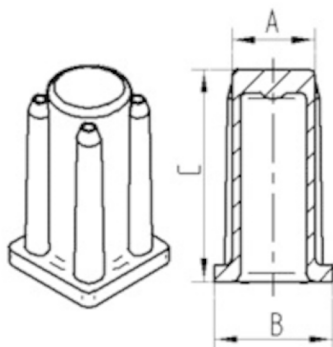

| Bezeichnung | A | B | C |
|-------------|----|------|----|
| R40-16x16 | 16 | 20 | 36 |
| R40-17x17 | 17 | 19 | 36 |
| R40-18x18 | 18 | 20 | 36 |
| R40-21x21 | 21 | 23,5 | 36 |
| R40-22x22 | 22 | 24,5 | 36 |
| R40-23x23 | 23 | 25,5 | 36 |
| R40-26x26 | 26 | 30 | 36 |