

INTEGRAL

2040UAX200R05-28 9002 W

EAN 4031582300147
Broj porudžbine 00030456



BETTER MOBILITY. BETTER LIFE.



Slika se može razlikovati od originalnog proizvoda

PERFORMANSE

Performanse kotrljanja	● ● ● ○ ○
Buka u pokretu	● ● ● ○ ○
Ishrana	● ● ● ● ○
otpornost na rdju	● ● ● ○ ○

OSNOVNI ATRIBUTI

Naziv proizvoda	Integral
Tip kućišta	Okretanje Tocak
Standard	EN12531 - Bolnički stolovi
Nosivost na 3 km/h	150 kg
Nosivost na 4 km/h	150 kg
Statički Nosivost	450 kg
Temperaturni opseg (Minimalno)	-25 °C
Opseg temperature (maksimalni)	80 °C
Sveukupna visina	229 mm
Ukupna širina	70 mm
Ukupna težina	1,554 kg
Sertifikacija	Ispitano i nadgledano od strane TÜV Süd

TOCAK

Materijal za telo	poliamid
materijal omotaca	Poliuretan, liveno
Nošenje	precizini kuglicni lezaj, zapečaceno
Boja omotac	Slat siva (RAL7015)
Boja Tocak	Slat siva (RAL7015)
stitnici omotaca	Integrisani threadguard
Prečnik	200 mm
Širina omotac	35 mm
Širina tela	35 mm
Teškoća gazećeg omotac (D)	59 Šor D

KUCISTE

Materijal	Čelični list, srednji
oblik viljuskas	Zatvoreno
okretni lezaj	precizini kuglicni lezaj
Boja	Siva bela (RAL9002)
ofset	60 mm
okretni radijus	160 mm
Otpor okretanju	320 mm
Prečnik kupole	70 mm

PRILAGOĐAVANJE

Tip uklapanja	stablo, okrugla
Prečnik sraf	28 mm
Dužina sraf	45 mm
Položaj sraf	19 mm
Količina otvora za montiranje sraf	2
Savet	Kreveti za pranje moraju biti zapečaceno u oblasti za montažu od strane proizvođača bolničkog kreveta.

DODATNE INFORMACIJE

Perivo prema AK-BWA



IF nagrada za
Dizajn



Red Dot Dizajn
Award

INTEGRAL




2040UAX200R05-28 9002 W

EAN 4031582300147
Broj porudžbine 00030456



BETTER MOBILITY. BETTER LIFE.

TEHNIČKI CRTEŽI

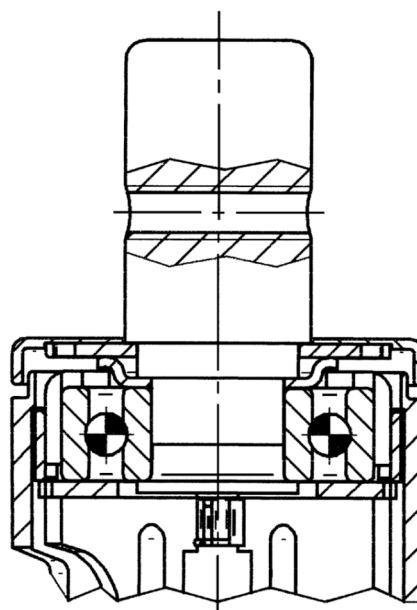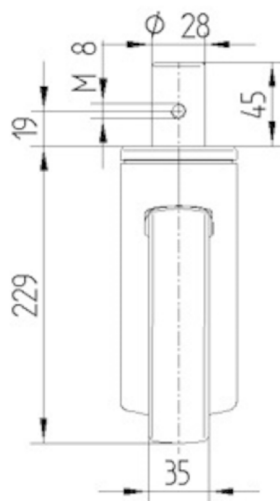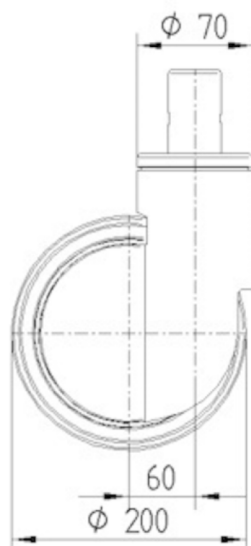

IF nagrada za
Dizajn



Red Dot Dizajn
Award