

# DURATECH

TOO200x50-Ø25

EAN 4031582322552

Telo tocka od poliamida, visoke nosivosti, obican lezaj

**TENTE**

BETTER MOBILITY. BETTER LIFE.



Picture may differ from original product


## Tehnicki podaci

Precnik tocka.	200 mm
Sirina gazista.	50 mm
Otvor za osovinu Ø	25 mm
Duzina glavcine.	60 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12533
Tezina	1.212 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	1000 kg
Staticka nosivost.	2000 kg

## Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○

## Dimensions

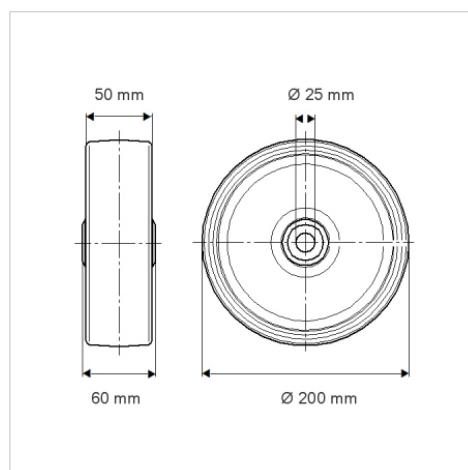

## Structure & Mounting

