

ELASTECH

UEP200x46-Ø12

EAN 4031582070378

Telo tocka od poliamida, Omotac: elasticna guam , crna , precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	200 mm
Sirina gazista.	46 mm
Otvor za osovinu Ø	12.5 mm
Duzina glavicine.	60 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	1.312 kg
Tvrdoca omotaca	Shore A 63
Dinamicka nosivost.	400 kg
Staticka nosivost.	800 kg

Dimensions

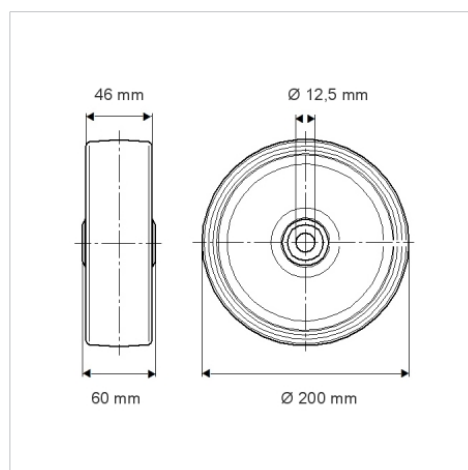

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ●
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○