

ELASTECH

UFP160x46-Ø12

EAN 4031582323368

Telo tocka od poliamida , Omotac: elasticna guma , ne ostavlja trag ,
precizni kuglicni lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	160 mm
Sirina gazista.	46 mm
Otvor za osovinu Ø	12.5 mm
Duzina glavcine.	60 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	0.943 kg
Tvrdoca omotaca	Shore A 63
Dinamicka nosivost.	300 kg
Staticka nosivost.	600 kg

Dimensions

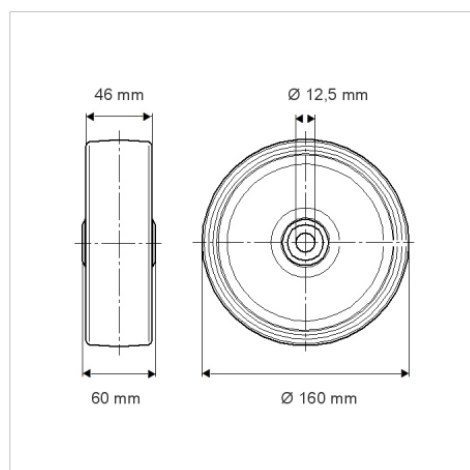

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ● ●
trenje , habanje	● ● ● ○ ○
zastita od korozije	● ● ● ○ ○