

DURATECH

U00080x34-Ø12

EAN 4031582070095

Telo tocka od poliamida , obican lezaj



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	34 mm
Otvor za osovinu Ø	12.1 mm
Duzina glavnice.	44.4 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12532
Tezina	0.078 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	200 kg
Staticka nosivost.	400 kg

Dimensions

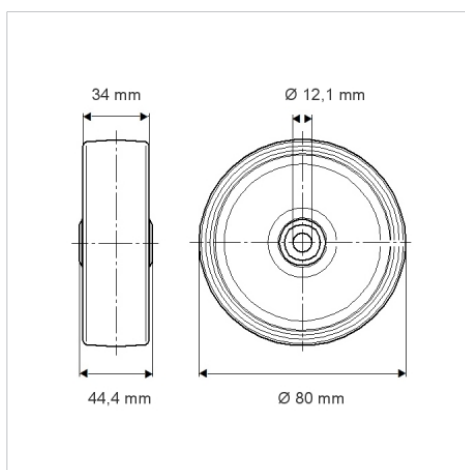

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○