

DURATECH

U00100x36-Ø12

EAN 4031582070101

Telo tocka od poliamida , obican lezaj

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	100 mm
Sirina gazista.	36 mm
Otvor za osovinu Ø	12.1 mm
Duzina glavcine.	44.4 mm
Temperatura	- 40 / + 80 °C
Standard	EN 12532
Tezina	0.135 kg
Tvrdoca omotaca	Shore D 75
Dinamicka nosivost.	200 kg
Staticka nosivost.	400 kg

Dimensions

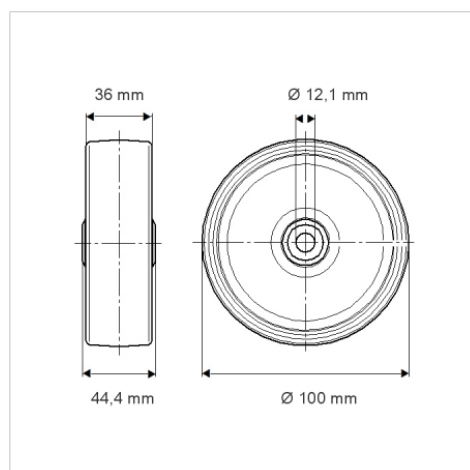

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ● ● ●
zastita od korozije	● ● ● ○ ○