

PURETECH

UVH080x35-Ø8

EAN 4031582323627

Telo tocka od poliamida , omotac: cvrsta , crna guma , obican lezaj sa ratkapanama.

TENTE

BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Tehnicki podaci

Precnik tocka.	80 mm
Sirina gazista.	35 mm
Otvor za osovinu Ø	8.3 mm
Duzina glavacine.	46 mm
Temperatura	- 20 / + 80 °C
Standard	EN 12532
Tezina	0.218 kg
Tvrdoca omotaca	Shore D 39
Dinamicka nosivost.	100 kg
Staticka nosivost.	200 kg

Dimensions

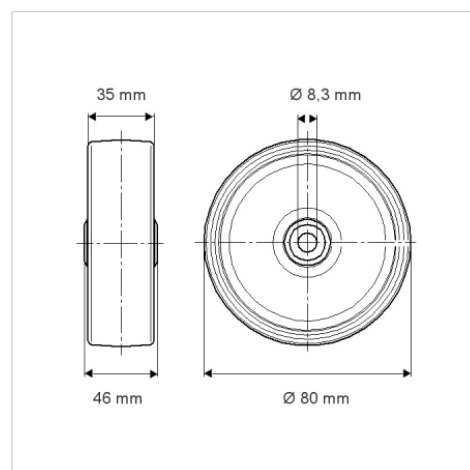

Advantages at a glance

Otpor okretanju	● ● ● ○ ○
Buka pri okretanju	● ● ● ○ ○
trenje , habanje	● ● ○ ○ ○
zastita od korozije	● ● ● ○ ○